


Outer shell	: Brass (UNS C38500)	Chrome plated (FS-QQ-C-320B)
Earthing crown	: Bronze (UNS C54400)	Nickel plated (FS-QQ-N-290A)
Insulator	: PEEK	-
Female contact	: Bronze (UNS C54400)	Gold plated (ISO 4523)
Notched nut	: Brass (UNS C38500)	Chrome plated (FS-QQ-C-320B)
Locking washer	: Bronze (UNS C52100)	Nickel plated (FS-QQ-N-290A)
Other metallic parts	: Brass (UNS C38500)	Nickel plated (FS-QQ-N-290A)

Panel cut-out

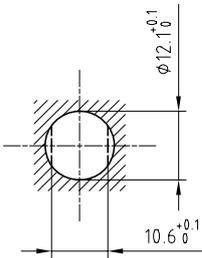

Torque for mounting nut : 4.5 Nm

Spanner for notched nut : DCH.91.161.PA

**Fixed socket , with two nuts , with key (G) .
(Back panel mounting) .
Series 1B , multipole (14)**

ETUDE N°

Echelle —	Dessiné	14.11.07	OVU / RMO
	Contrôle	14.11.07	RMO / CDE
	Modif.	00	14.11.07 / OVU



LEMO

CH-1024 Ecublens

ECG.1B.314.CLL