

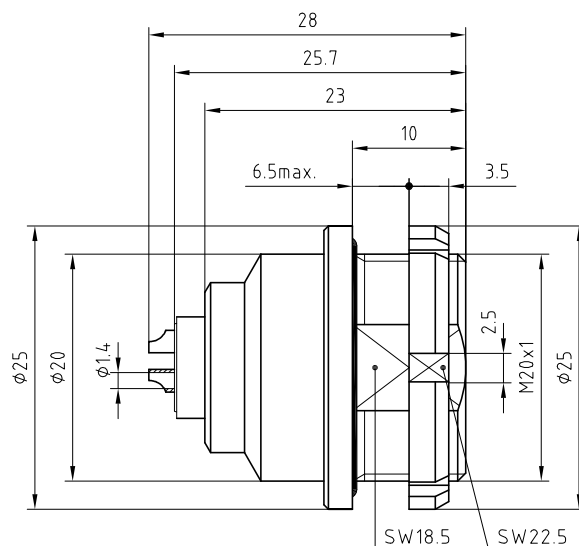


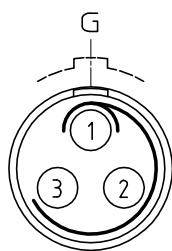

Outer shell	: Brass (UNS C38500)	Chrome plated (FS-QQ-C-320B)
Earthing crown	: Brass (UNS C38500)	Nickel plated (FS-QQ-N-290A)
Insulator	: PEEK	-
Female contact	: Bronze (UNS C54400)	Gold plated (ISO 27874)
Notched nut	: Brass (UNS C38500)	Chrome plated (FS-QQ-C-320B)
Other metallic part	: Brass (UNS C38500)	Nickel plated (FS-QQ-N-290A)
O-rings	: Silicone (MVQ)	-

Panel cut-out

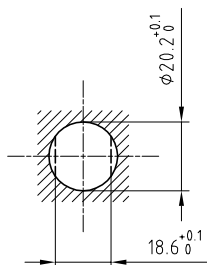

Torque for
mounting
nut : 9 Nm

Spanner for notched nut : DCH.91.251.PA

Fixed socket , nut fixing , with key (G) .
(Back panel mounting) .
Series 2K , multipole (3)

ETUDE N° E1826-E9179

Echelle

Dessiné 28.03.2018 OVU / NHA

Contrôle 28.03.2018 NHA / ATVI

Modif. 00 28.03.2018/ OVU



LEMO

LEMO SA
Chemin des Champs-Courbes 28
1024 Ecublens - SWITZERLAND

Tel. (+41 21) 695 16 00
email : info@lemo.com
www.lemo.com

EEG.2K.303.CLL