





1

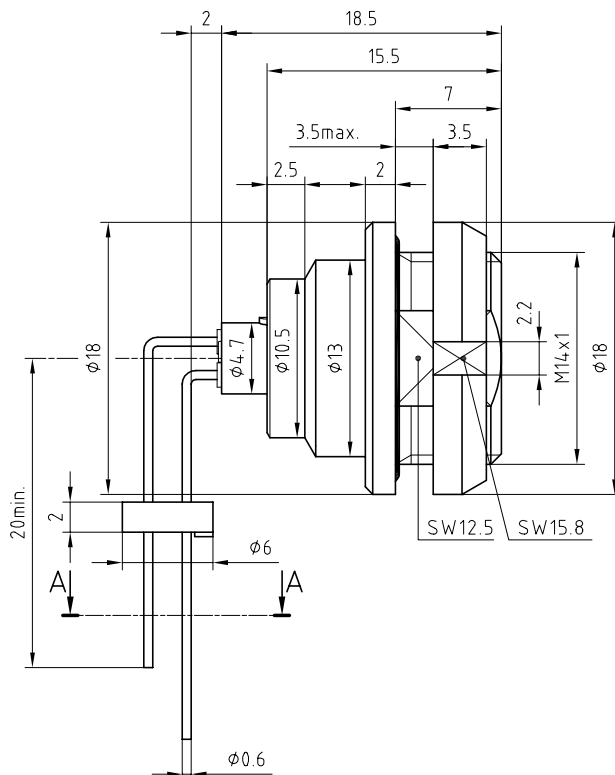

|                     |                       |                              |
|---------------------|-----------------------|------------------------------|
| Outer shell         | : Brass (UNS C38500)  | Chrome plated (FS-QQ-C-320B) |
| Earthing crown      | : Bronze (UNS C54400) | Nickel plated (FS-QQ-N-290A) |
| Insulator           | : PEEK                | -                            |
| Male contact        | : Brass (UNS C34500)  | Gold plated (ISO 4523)       |
| Clip                | : Cu-Be (UNS C17200)  | -                            |
| Notched nut         | : Brass (UNS C38500)  | Chrome plated (FS-QQ-C-320B) |
| Other metallic part | : Brass (UNS C38500)  | Nickel plated (FS-QQ-N-290A) |
| O-rings             | : Silicone (MVQ)      | -                            |
| Contact wire        | : Bronze (UNS C27400) | Tinned                       |
| Position insert     | : FEP                 | -                            |

A-A cross-section (PCB drilling pattern)

Torque for  
mounting  
nut : 5 Nm

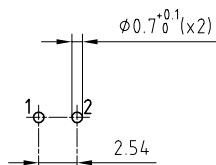

Echelle

OVU / RMO

RMO / CDE

02.06.06 / OVU



**LENOVA**

CH-1024 Ecublens

EEL.0K.302.CL V