



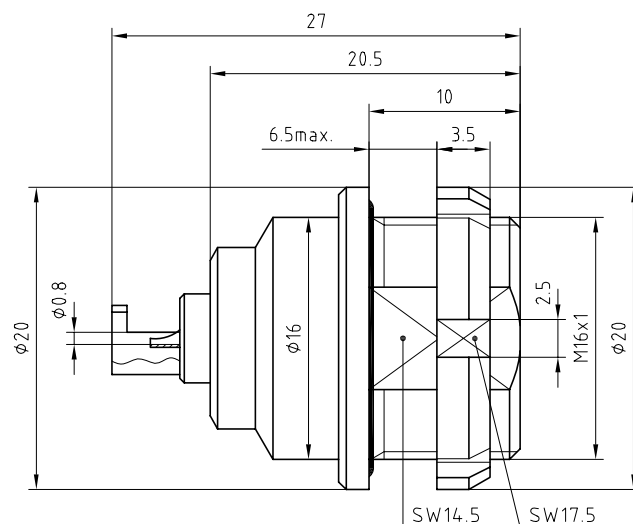

Outer shell	: Brass (UNS C38500)	Chrome plated (FS-QQ-C-320B)
Earthing crown	: Bronze (UNS C54400)	Gold plated (ISO 4523)
Insulators	: PTFE	-
Male sleeve	: Brass (UNS C38500)	Gold plated (ISO 4523)
Female contact	: Bronze (UNS C54400)	Gold plated (ISO 4523)
Notched nut	: Brass (UNS C38500)	Chrome plated (FS-QQ-C-320B)
Other metallic part	: Brass (UNS C38500)	Nickel plated (FS-QQ-N-290A)
O-rings	: Silicone (MVQ)	-

Panel cut-out

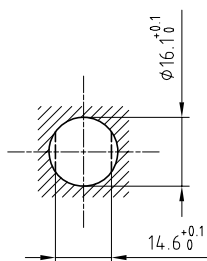

Torque for
mounting
nut : 7 Nm

Spanner for notched nut : DCH.91.201.PA

Fixed socket , with nut fixing .
(Back panel mounting) .
Series 1E , triaxial (50Ω)

ETUDE N° E1826

Echelle

Dessiné

04.09.06

OVU / RMO

Contrôle

04.09.06

RMO / CDE

Modif.

00

04.09.06 / OVU



LEMO

CH-1024 Ecublens

EEP.1E.650.CTL