

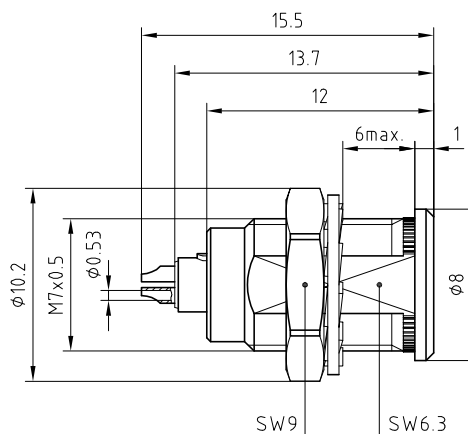


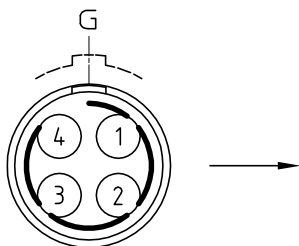

Outer shell	: Brass (UNS C38500)	Chrome plated (FS-QQ-C-320B)
Earthing crown	: Cu-Be (UNS C17300)	Nickel plated (FS-QQ-N-290A)
Insulator	: PEEK	-
Female contact	: Bronze (UNS C54400)	Gold plated (ISO 27874)
Locking washer	: Bronze (UNS C52100)	Nickel plated (FS-QQ-N-290A)
Other metallic parts	: Brass (UNS C38500)	Nickel plated (FS-QQ-N-290A)

Panel cut-out

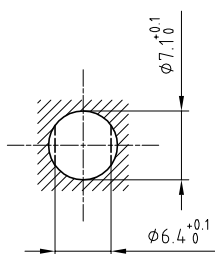

Torque for
mounting
nut : 1 Nm

Spanner for nut : DCA.91.149.0TN or
Spanner for nut : DCG.91.149.0TN

**Fixed socket , with nut , with key (G) .
Series 00 , multipole (4)**

ETUDE N° E1347-E6207

Echelle —	Dessiné	18.06.2003	OVU / RMO
	Contrôle	17.08.2016	NHA / ATVI
	Modif.	02	17.08.2016/ OVU



LEMO

CH-1024 Ecublens

EGG.00.304.CLL