

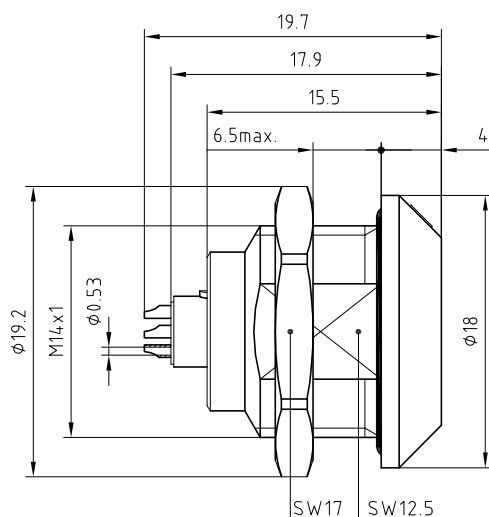


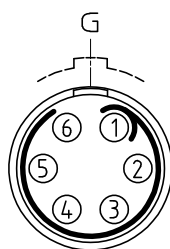

Outer shell	: Brass (UNS C38500)	Chrome plated (SAE AMS 2460)
Earthing crown	: Bronze (UNS C54400)	Nickel plated (SAE AMS QQ N 290)
Insulator	: PEEK	-
Female contact	: Bronze (UNS C54400)	Gold plated (ISO 27874)
Other metallic part	: Brass (UNS C38500)	Nickel plated (SAE AMS QQ N 290)
O-rings	: Silicone (MVQ)	-

Panel cut-out

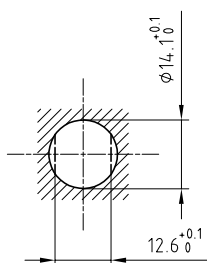

Torque for
mounting
nut : 5 Nm

Fixed socket with nut fixing , with key (G) ,
Series OK , multipole (6)

ETUDE N° E6041-E7218-E6207-E6218

Echelle —	Dessiné	14.04.2020	OVU / NHA
	Contrôle	14.04.2020	NHA / CDE
	Modif.	00	14.04.2020/ OVU



LEMO

LEMO SA
Chemin des Champs-Courbes 28
1024 Ecublens - SWITZERLAND

Tel. (+41 21) 695 16 00
email : info@lemo.com
www.lemo.com

EGG.OK.306.CLL