


| | | |
|----------------------|----------------------|------------------------------|
| Outer shell | : Brass (UNS C38500) | Chrome plated (FS-QQ-C-320B) |
| Earthing crown | : Brass (UNS C38500) | Nickel plated (FS-QQ-N-290A) |
| Insulator | : PEEK-PDX-L-97024 | - |
| Other metallic parts | : Brass (UNS C38500) | Nickel plated (FS-QQ-N-290A) |
| O-Rings | : MVQ | - |

Panel cut-out

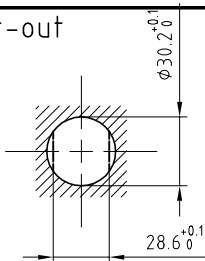

Torque for mounting nut : 17 Nm

Parts that must be ordered separately :

Fiber-optic contact ref : PSS.F2.BB2.LCT10 or ...E30 ferrule hole 126µm
 Fiber-optic contact ref : PSS.F2.BA2.LCT10 or ...E30 ferrule hole 125µm

**Fixed socket with nut fixing ,
 with key (G) .
 Series 4K , 4FO(typeF2)**

ETUDE N° E6186

Echelle

| | | |
|----------|----------|----------------|
| Dessiné | 14.10.99 | OVU / JCHU |
| Contrôle | 11.09.03 | RMO / CDE |
| Modif. | 01 | 11.09.03 / OVU |



LEMO

CH-1024 Ecublens

EGG.4K.03C.CLZ