

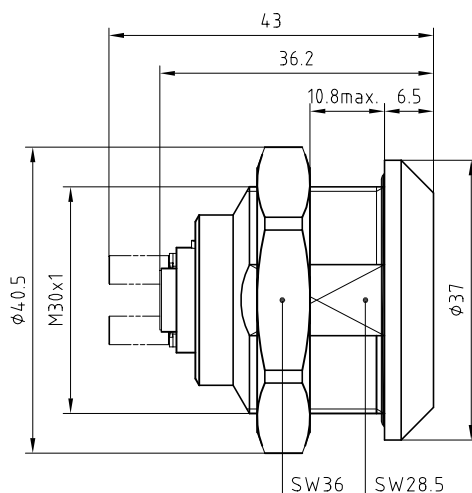


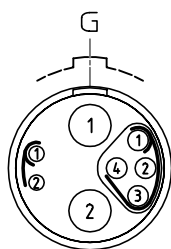

Outer shell	: Brass (UNS C38500)	Chrome plated (FS-QQ-C-320B)
Earthing crown	: Brass (UNS C38500)	Nickel plated (FS-QQ-N-290A)
Insulator	: PEEK-PDX-L-97024	-
Female contacts (LV)	: Bronze (UNS C54400)	Gold plated (ISO 4523)
Clips	: Cu-Be (UNS C17200)	-
Other metallic parts	: Brass (UNS C38500)	Nickel plated (FS-QQ-N-290A)
O-Rings	: Silicone (MVQ)	-

Panel cut-out

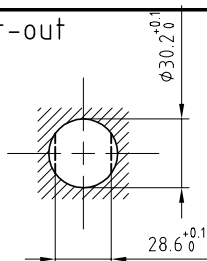

Torque for
mounting
nut : 17 Nm

Parts that must be ordered separately :

Fiber-optic contact ref : PSS.F2.BB2.LCT10 or ...E30 ferrule hole 126µm
Fiber-optic contact ref : PSS.F2.BA2.LCT10 or ...E30 ferrule hole 125µm

Assembly instruction per document n° __

**Fixed socket with nut fixing ,
with key (G) .**
Séries 4K , 2FO(typeF2) + 2LV(Ø0.9) + 4LV(Ø1.3)

ETUDE N° E2051

Echelle

Dessiné

23.02.05

OVU / JCHU

Contrôle

23.02.05

RM0 / CDE

Modif.

00

23.02.05 / OVU



LEMO

CH-1024 Ecublens

EGG.4K.93E.CLM