



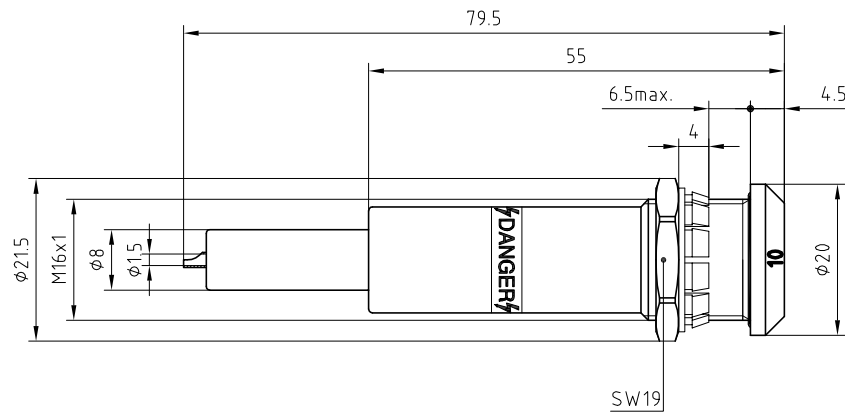

Outer shell	: Brass (UNS C38500)	Chrome plated (FS-QQ-C-320B)
Earthing crown	: Cu-Be (UNS C17200)	Gold plated (ISO 27874)
Insulator	: PTFE	-
Male contact	: Brass (UNS C38500)	Gold plated (ISO 27874)
Tapered washer	: Brass (UNS C38500)	Nickel plated (FS-QQ-N-290A)
Other metallic parts	: Brass (UNS C38500)	Nickel plated (FS-QQ-N-290A)
O-Ring	: Silicone (MVQ)	-
Label	: Polyester	Yellow

Panel cut-out

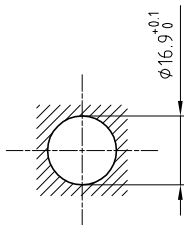

Torque for
mounting
nut : 7 Nm

Fixed socket , nut fixing .
Series 1Y , (1) HV(Ø1.4)

ETUDE N° E879

Echelle —	Dessiné	24.08.2005	OVU / RMO
	Contrôle	20.03.2018	NHA / ATVI
	Modif.	03	20.03.2018/ OVU



LEMO

LEMO SA
Chemin des Champs-Courbes 28
1024 Ecublens - SWITZERLAND

Tel. (+41 21) 695 16 00
email : info@lemo.com
www.lemo.com

ERA.1Y.410.CTA