


Outer shell	: Brass (UNS C38500)	Chrome plated (FS-QQ-C-320B)
Earthing crown	: Brass (UNS C38500)	Gold plated (ISO 27874)
Insulator	: PTFE	-
Femelle contact	: Bronze (UNS C54400)	Gold plated (ISO 27874)
Other metallic parts	: Brass (UNS C38500)	Nickel plated (FS-QQ-N-290A)
O-rings	: Silicone (MVQ)	-

Panel cut-out

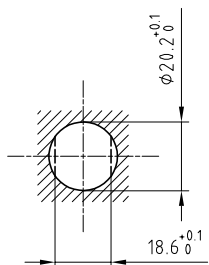

Torque for mounting nut : 9 Nm

Fixed socket , with nut fixing .
Series 2E , coaxial (75Ω)

ETUDE N° E6041

Echelle	Dessiné	09.05.2019	OVU / NHA
	Contrôle	09.05.2019	NHA / ATVI
	Modif.	00	09.05.2019/ OVU



LEMO

LEMO SA
Chemin des Champs-Courbes 28
1024 Ecublens - SWITZERLAND

Tel. (+41 21) 695 16 00
email : info@lemo.com
www.lemo.com

ERA.2E.275.CTL