

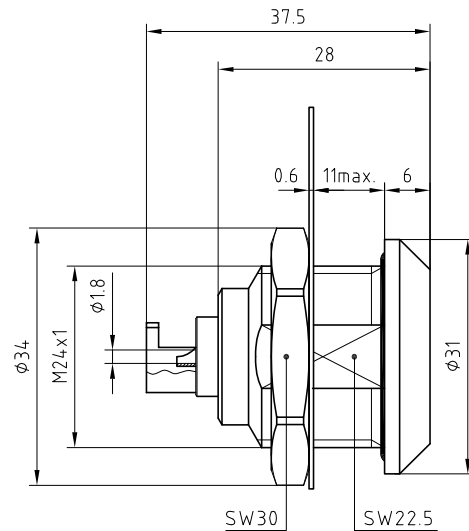


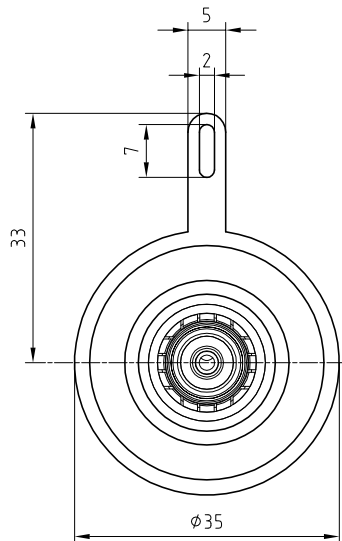


Outer shell	: Brass (UNS C38500)	Chrome plated (FS-QQ-C-320B)
Earthing crown	: Brass (UNS C38500)	Gold plated (ISO 4523)
Insulators	: PTFE	-
Female sleeve	: Brass (UNS C38500)	Gold plated (ISO 4523)
Female contact	: Bronze (UNS C54400)	Gold plated (ISO 4523)
Earthing washer	: Brass (UNS C27400)	CuSnZn plated
Other metallic parts	: Brass (UNS C38500)	Nickel plated (FS-QQ-N-290A)
O-rings	: Silicone (MVQ)	-

Panel cut-out

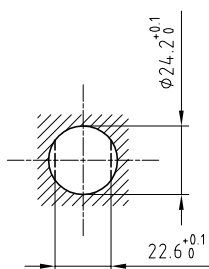

Torque for
mounting
nut : 12 Nm

Stripping dimensions

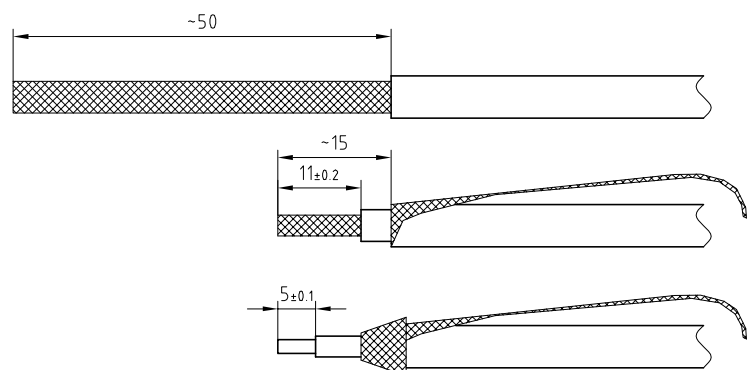

**Fixed socket , with nut fixing .
Series 3E , triaxial (50Ω)**

ETUDE N° E870-E9807

Echelle —	Dessiné	03.09.2010	OVU / JPBA
	Contrôle	03.09.2010	JPBA / ATVI
	Modif.	00	03.09.2010/ OVU



LEMO

CH-1024 Ecublens

ERA.3E.650.CTL