


DANGER

Outer shell	: Brass (UNS C38500)	Chrome plated (FS-QQ-C-320B)
Earthing crown	: Bronze (UNS C54400)	Gold plated (ISO 27874)
Insulator	: PTFE	-
Female contact	: Cu-Be (UNS C17300)	Gold plated (ISO 27874)
Locking washer	: Bronze (UNS C52100)	Nickel plated (FS-QQ-N-290A)
Other metallic parts	: Brass (UNS C38500)	Nickel plated (FS-QQ-N-290A)
Label	: Polyester	Yellow

Panel cut-out

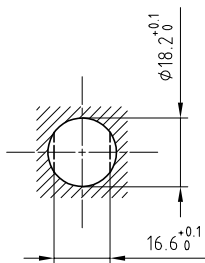

Torque for mounting nut : 9 Nm

Spanner for nut : DCA.91.282.2TN or
Spanner for nut : DCG.91.282.2TN

**Fixed socket , with nut fixing .
Series 3S , (1) HV(φ1.3)**

Echelle —	Dessiné	05.01.2006	BC / RMO
	Contrôle	16.05.2019	NHA / ATVI
	Modif.	02	16.05.2019/ OVU

ETUDE N° E894



LEMO

LEMO SA
Chemin des Champs-Courbes 28
1024 Ecublens - SWITZERLAND

Tel. (+41 21) 695 16 00
email : info@lemo.com
www.lemo.com

ERA.3S.415.CTL