



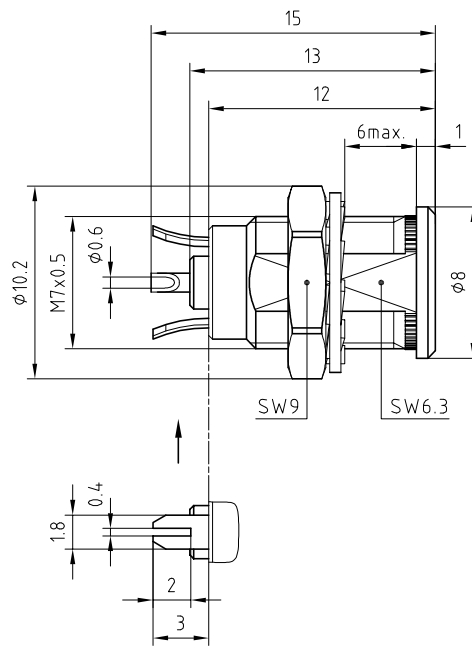

Outer shell	: Brass (UNS C38500)	Chrome plated (FS-QQ-C-320B)
Earthing crown	: Cu-Be (UNS C17300)	Nickel plated (FS-QQ-N-290A)
Insulator	: PTFE	-
Female contact	: Bronze (UNS C54400)	Gold plated (ISO 27874)
Hexagonal nut	: Brass (UNS C38500)	Nickel plated (FS-QQ-N-290A)
Locking washer	: Bronze (UNS C52100)	Nickel plated (FS-QQ-N-290A)
Earthing tags	: Brass (UNS C34200)	Nickel plated (FS-QQ-N-290A)

Panel cut-out

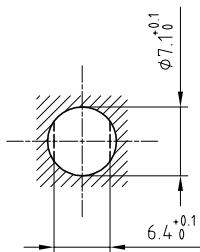

Torque for
mounting
nut : 1 Nm

Spanner for nut : DCA.91.149.0TN or
Spanner for nut : DCG.91.149.0TN

Fixed socket with nut fixing , with tags .
Series 00 , coaxial (50 Ω)

ETUDE N°

Echelle —	Dessiné	05.10.1993	XK0 / RMO
	Contrôle	26.03.2018	NHA / ATVI
	Modif.	03	26.03.2018/ OVU



LEMO

LEMO SA
Chemin des Champs-Courbes 28
1024 Ecublens - SWITZERLAND

Tel. (+41 21) 695 16 00
email : info@lemo.com
www.lemo.com

ERN.00.250.CTL