

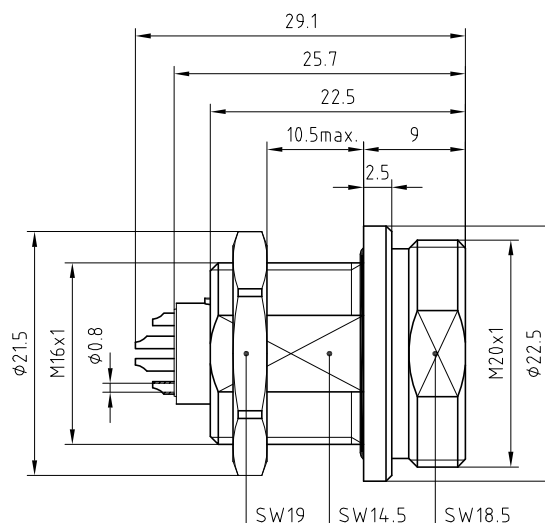


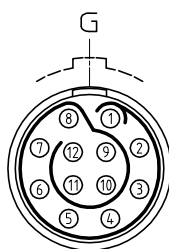

Outer shell	: Brass (UNS C38500)	Chrome plated (FS-QQ-C-320B)
Earthing crown	: Brass (UNS C38500)	Nickel plated (FS-QQ-N-290A)
Insulator	: PEEK	-
Female contact	: Bronze (UNS C54400)	Gold plated (ISO 27874)
Hexagonal nut	: Brass (UNS C38500)	Nickel plated (FS-QQ-N-290A)
Other metallic part	: Brass (UNS C38500)	Nickel plated (FS-QQ-N-290A)
O-ring	: Viton (FPM)	-

Panel cut-out

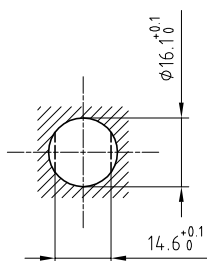

Torque for
mounting
nut : 7 Nm

**Fixed socket , nut fixing . with key (G) .
Series 2W , multipole (12)**

ETUDE N° E6212

Echelle —	Dessiné	09.10.2017	OVU / NHA
	Contrôle	09.10.2017	NHA / ATVI
	Modif.	00	09.10.2017/ OVU



LEMO

LEMO SA
Chemin des Champs-Courbes 28
1024 Ecublens - SWITZERLAND

Tel. (+41 21) 695 16 00
email : info@lemo.com
www.lemo.com

EVG.2W.312.CLL