



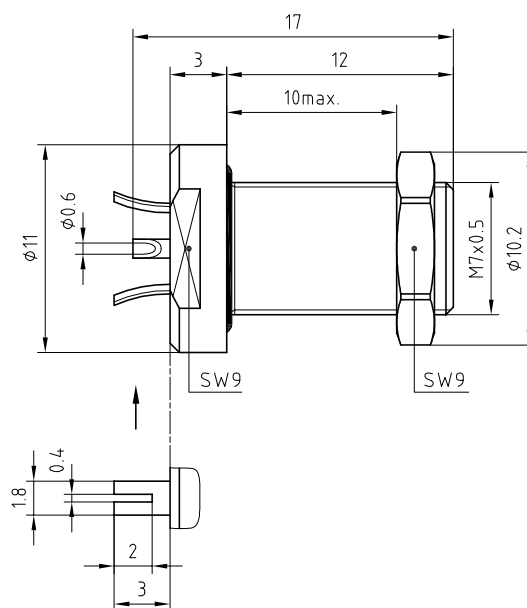

Outer shell	: Brass (UNS C38500)	Nickel plated (FS-QQ-N-290A)
Earthing crown	: Cu-Be (UNS C17300)	Gold plated (ISO 27874)
Insulator	: PTFE	-
Female contact	: Bronze (UNS C54400)	Gold plated (ISO 27874)
Hexagonal nut	: Brass (UNS C38500)	Nickel plated (FS-QQ-N-290A)
Earthing tags	: Brass (UNS C34200)	Nickel plated (FS-QQ-N-290A)
Sealing resin	: Epoxy	-
O-ring	: Viton (FPM)	-

Panel cut-out

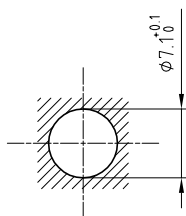

Torque for
mounting
nut : 1 Nm

Spanner for nut : DCG.91.149.0TN

**Fixed socket with earthing tags , nut fixing ,
vacuumtight . (Back panel mounting) .
Series 00 , coaxial (50Ω)**

ETUDE N° E4278-E3126-E9018

Echelle —	Dessiné	04.02.2002	BC / RMO
	Contrôle	27.03.2018	NHA / ATVI
	Modif.	03	27.03.2018/ OVU



LEMO

LEMO SA
Chemin des Champs-Courbes 28
1024 Ecublens - SWITZERLAND

Tel. (+41 21) 695 16 00
email : info@lemo.com
www.lemo.com

EWf.00.250.NTLPV