
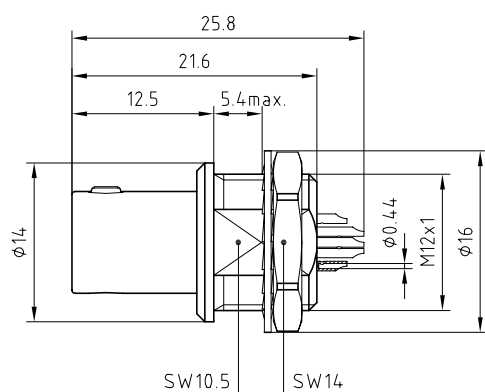


Outer shell	: Brass (UNS C38500)	Chrome plated (FS-QQ-C-320B)
Insulator	: PEEK	-
Male contact	: Brass (UNS C38500)	Gold plated (ISO 4523)
Locking washer	: Bronze (UNS C52100)	Nickel plated (FS-QQ-N-290A)
Other metallic parts	: Brass (UNS C38500)	Nickel plated (FS-QQ-N-290A)

Panel cut-out

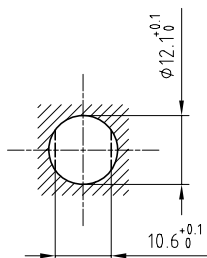

Torque for mounting
nut : 4.5 Nm

Spanner for nut : DCA.91.201.4 TN or
Spanner for nut : DCG.91.201.4 TN

**Fixed plug , non-latching , nut fixing ,
with key (G) .
Series 1B , multipole (14)**

ETUDE N°

Echelle

—

Dessiné	14.11.07	OVU / RMO
Contrôle	14.11.07	RMO / CDE
Modif.	00	14.11.07 / OVU



LEMO

CH-1024 Ecublens

FAG.1B.314.CLA