


Outer shell	: Brass (UNS C38500)	Chrome plated (FS-QQ-C-320B)
Insulator	: PEEK	-
Male contact	: Brass (UNS C38500)	Gold plated (ISO 4523)
Locking washer	: Bronze (UNS C52100)	Nickel plated (FS-QQ-N-290A)
Other metallic parts	: Brass (UNS C38500)	Nickel plated (FS-QQ-N-290A)

Panel cut-out

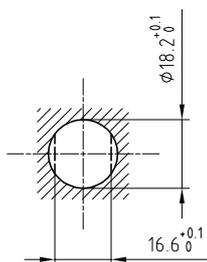

Torque for mounting nut : 9 Nm

Spanner for nut : DCA.91.282.2TN or
Spanner for nut : DCG.91.282.2TN

**Fixed plug , non-latching , nut fixing ,
with key (G) .**

Series 3B , multipole (14)

ETUDE N° E1286A

Echelle —	Dessiné	20.04.2010	OVU /JPBA
	Contrôle	20.04.2010	JPBA/ CDE
	Modif.	00	20.04.2010/ OVU



LEMO

CH-1024 Ecublens

FAG.3B.314.CLA