


View of insert

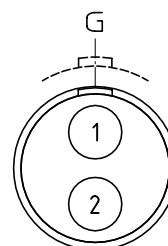

Section of adapter for two cables



Outer shell	: Brass (UNS C38500)	Chrome plated (FS-QQ-C-320B)
Latch sleeve	: Special brass	Chrome plated (FS-QQ-C-320B)
Inner shell	: Brass (UNS C38500)	Nickel plated (FS-QQ-N-290A)
Collet nut	: Brass (UNS C38500)	Chrome plated (FS-QQ-C-320B)
Insulator	: PEEK-PDX-L-97024	-
Other metallic parts	: Brass (UNS C38500)	Nickel plated (FS-QQ-N-290A)
O-Ring	: NBR	-
Bend relief	: Polyurethan	Various colors

Parts that must be ordered separately :  
Fiber-optic contact ref : FFS.F2.BB2.LCE30 ferrule hole 126µm

Assembly instruction per document n° \_\_

**Straight plug , with key (G) , cable adapter  
and nut for fitting for two cables a bend relief .  
Series 3K , 2FO(typeF2)**

ETUDE N° E9058

Echelle —	Dessiné	10.03.04	OVU / RMO
	Contrôle	10.03.04	RMO / CDE
	Modif.	00	10.03.04 / OVU



**LEMO**

CH-1024 Ecublens

**FGG.3K.03A.CLZW40Z**