


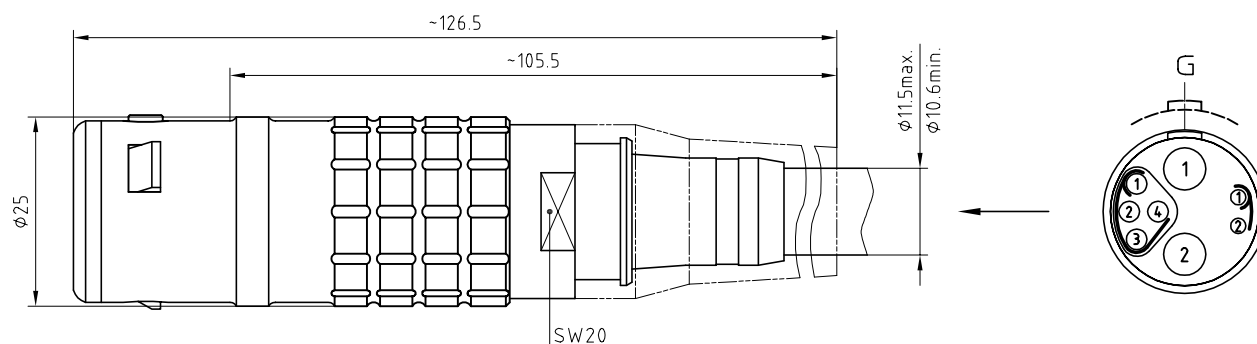

Outer shell	: Brass (UNS C38500)	Chrome plated (FS-QQ-C-320B)
Latch sleeve	: Special brass	Chrome plated (FS-QQ-C-320B)
Inner shell	: Brass (UNS C38500)	Nickel plated (FS-QQ-N-290A)
Collet nut	: Brass (UNS C38500)	Chrome plated (FS-QQ-C-320B)
Insulator	: PEEK-PDX-L-97024	-
Male contacts (LV)	: Brass (UNS C34500)	Gold plated (ISO 4523)
Clips	: Cu-Be (UNS C17200)	-
Other metallic parts	: Brass (UNS C38500)	Nickel plated (FS-QQ-N-290A)
O-ring	: Viton (FPM)	-
Bend relief	: Polyurethan	Various colors

Parts that must be ordered separatly :
 Fiber-optic contact ref : FFS.F2.BB2.LCT10 or ...E30 ferrule hole 126µm
 Fiber-optic contact ref : FFS.F2.BA2.LCT10 or ...E30 ferrule hole 125µm
 Bend relief réf : GMA.4B.011.D__

Assembly instruction per document n° __

**Straight plug , with key (G) , cable collet adapter
 and nut for fitting a bend relief .
 Series 4K , 2FO(typeF2) + 2LV(Ø0.9) + 4LV(Ø1.3)**

ETUDE N° E2051

Echelle —	Dessiné	23.02.05	OVU / RMO
	Contrôle	23.02.05	RMO / CDE
	Modif.	00	23.02.05 / OVU



LEMO

CH-1024 Ecublens

FGG.4K.93E.CLCT11Z