

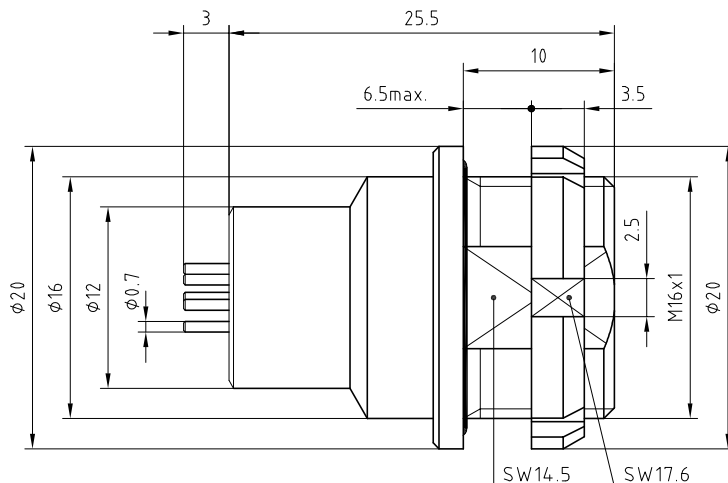


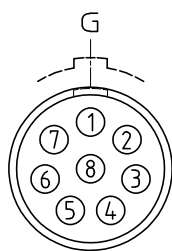


Outer shell	: Brass (UNS C38500)	Chrome plated (SAE AMS 2460)
Earthing crown	: Bronze (UNS C54400)	Nickel plated (SAE AMS QQ N 290)
Insulator	: PEEK	-
Female contact	: Bronze (UNS C54400)	Gold plated (ISO 27874)
Notched nut	: Brass (UNS C38500)	Chrome plated (SAE AMS 2460)
Other metallic part	: Brass (UNS C38500)	Nickel plated (FS-QQ-N-290A)
Sealing resin	: Epoxy	-
O-rings	: Silicone (MVQ)	-

Panel cut-out

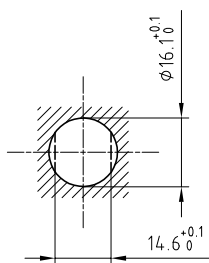

Torque for mounting nut : 7 Nm

A-A cross-section (PCB drilling pattern)

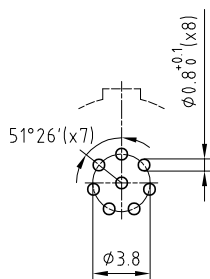

Spanner for notched nut : DCH.91.201.PA

Fixed socket , nut fixing , with key (G) , watertight , for PCB . (Back panel mounting) . Series 1K , multipole (8)

ETUDE N° E9205-E2429-E7114

Echelle

Dessiné	04.06.2020	OVU / NHA
Contrôle	04.06.2020	NHA / CDE
Modif.	00	04.06.2020 / OVU



LEMO

LEMO SA
Chemin des Champs-Courbes 28
1024 Ecublens - SWITZERLAND

Tel. (+41 21) 695 16 00
email : info@lemo.com
www.lemo.com

HEG.1K.308.CLNP