

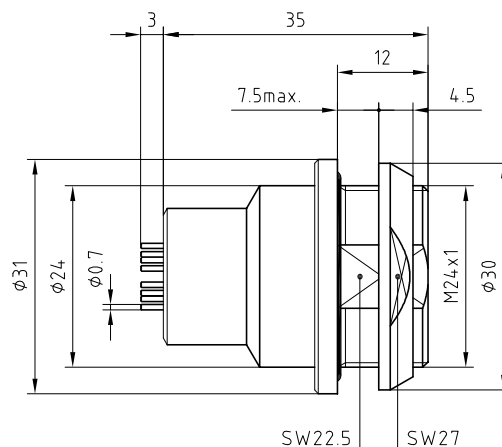


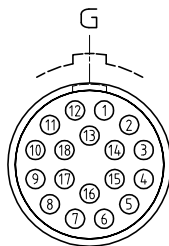


Outer shell	: Brass (UNS C38500)	Chrome plated (FS-QQ-C-320B)
Earthing crown	: Brass (UNS C38500)	Nickel plated (FS-QQ-N-290A)
Insulator	: PEEK	-
Female contact	: Bronze (UNS C54400)	Gold plated (ISO 27874)
Conical nut	: Brass (UNS C38500)	Chrome plated (FS-QQ-C-320B)
Other metallic part	: Brass (UNS C38500)	Nickel plated (FS-QQ-N-290A)
Sealing resin	: Epoxy	-
O-rings	: Silicone (MVQ)	-

Panel cut-out

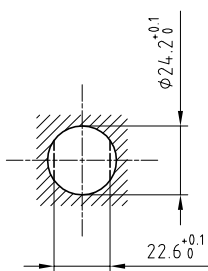

Torque for
mounting
nut : 12 Nm

PCB drilling pattern

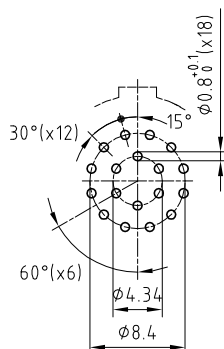

-

**Fixed socket , nut fixing , with key (G) ,
watertight , for PCB . (Back panel mounting) .
Series 3K , multipole (18)**

ETUDE N° E11081-E10981-E1740

Echelle

Dessiné	15.03.2018	OVU / NHA
Contrôle	15.03.2018	NHA / ATVI
Modif.	00	15.03.2018/ OVU



LEMO

LEMO SA
Chemin des Champs-Courbes 28
1024 Ecublens - SWITZERLAND

Tel. (+41 21) 695 16 00
email : info@lemo.com
www.lemo.com

HEG.3K.318.CLNP