



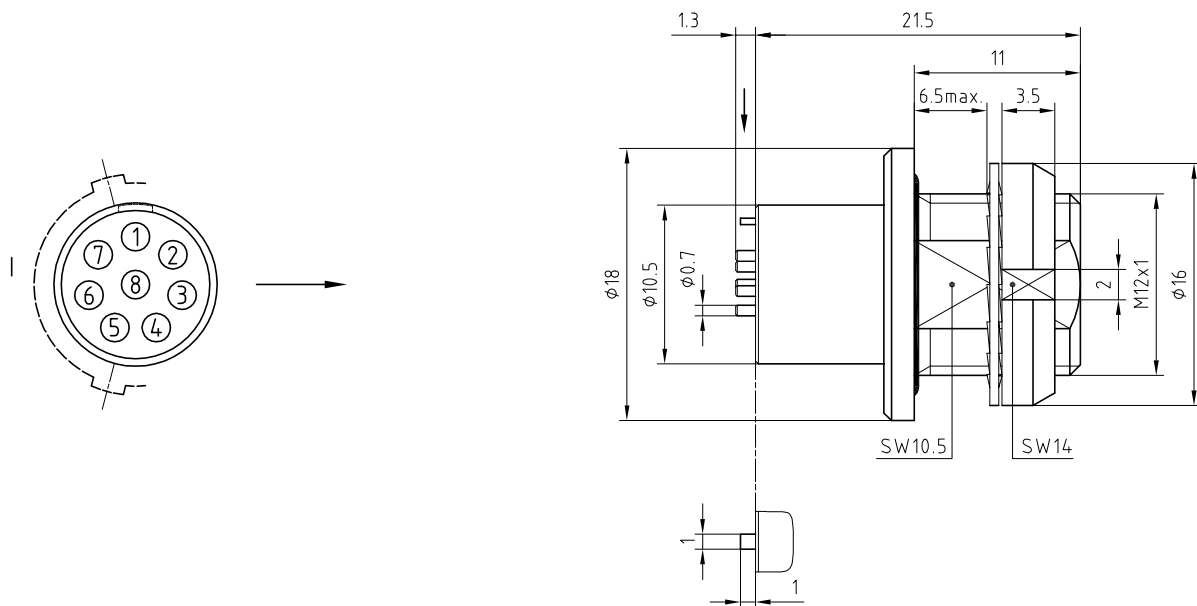


Outer shell	: Brass (UNS C38500)	Chrome plated (FS-QQ-C-320B)
Earthing crown tag	: Bronze (UNS C54400)	Gold plated (ISO 27874)
Insulator	: PEEK	-
Female contact	: Bronze (UNS C54400)	Gold plated (ISO 27874)
Notched nut	: Brass (UNS C38500)	Chrome plated (FS-QQ-C-320B)
Locking washer	: Bronze (UNS C52100)	Nickel plated (FS-QQ-N-290A)
Sealing resin	: Epoxy	-
O-ring	: Silicone (MVQ)	-

Panel cut-out

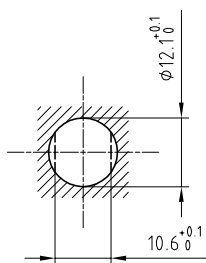

Torque for
mounting
nut : 4.5 Nm

PCB drilling pattern

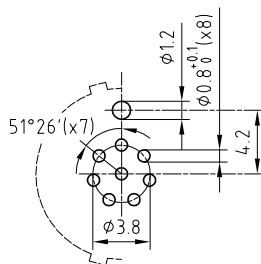

Spanner for notched nut : DCH.91.161.PA

**Fixed socket with earthing tag , nut fixing , with keys (I) ,
watertight , for PCB . (Back panel mounting) .
Series 1B , multipole (8) (Special contact and tag length)**

ETUDE N° E3254-E7187-E1477

Echelle

Dessiné 10.06.2014 OVU / JPBA

Contrôle 10.06.2014 JPBA / ATVI

Modif. 00 10.06.2014/ OVU



LEMO

CH-1024 Ecublens

HMI.1B.308.CL YP