

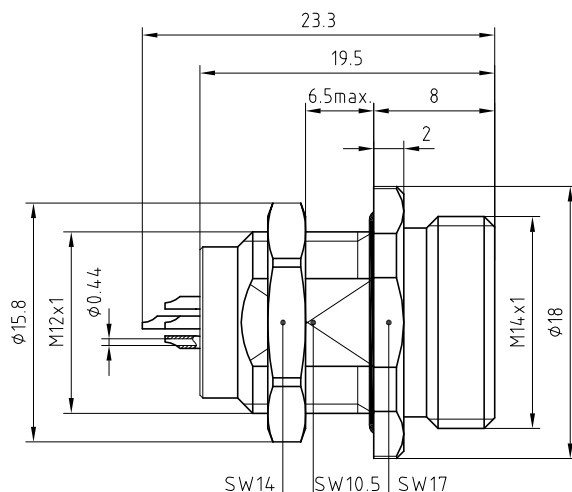


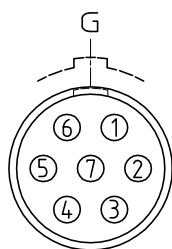

Outer shell	: Brass (UNS C38500)	Chrome plated (FS-QQ-C-320B)
Earthing crown	: Bronze (UNS C54400)	Nickel plated (FS-QQ-N-290A)
Insulator	: PEEK	-
Female contact	: Bronze (UNS C54400)	Gold plated (ISO 27874)
Other metallic parts	: Brass (UNS C38500)	Nickel plated (FS-QQ-N-290A)
Sealing resin	: Epoxy	-
O-ring	: Viton (FPM)	-

Panel cut-out

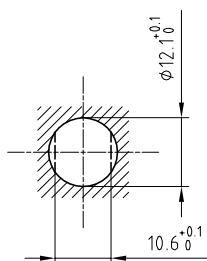

Torque for
mounting
nut : 4.5 Nm

Fixed socket, nut fixing , with key (G) , hexagonal flange ,
with flats on fixing thread , vacuumtight .

Series 0W , multipole (7)

ETUDE N° E2413-E1549-E7128

Echelle

Dessiné 24.07.2015 OVU / NHA

Contrôle 24.07.2015 NHA / ATVI

Modif. 00 24.07.2015/ OVU



LEMO

CH-1024 Ecublens

HRG.0W.307.CLLPV