

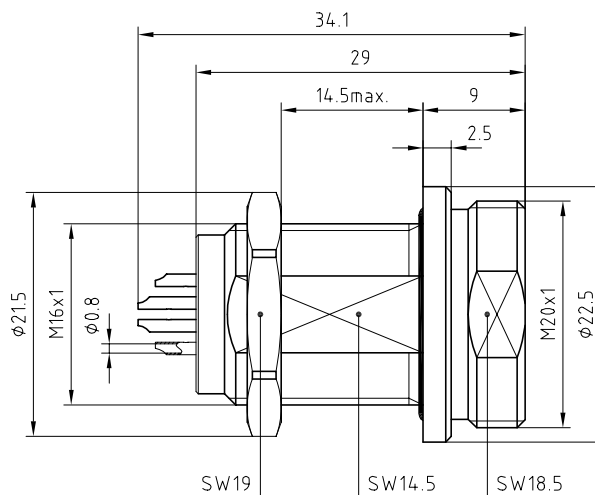


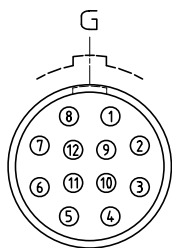

Outer shell	: Brass (UNS C38500)	Chrome plated (FS-QQ-C-320B)
Earthing crown	: Brass (UNS C38500)	Nickel plated (FS-QQ-N-290A)
Insulator	: PEEK	-
Female contact	: Bronze (UNS C54400)	Gold plated (ISO 4523)
Other metallic parts	: Brass (UNS C38500)	Nickel plated (FS-QQ-N-290A)
Sealing resin	: Epoxy	-
O-ring	: Viton (FPM)	-

Panel cut-out

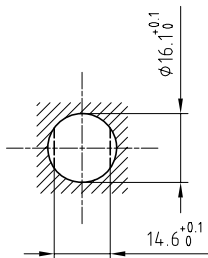

Torque for
mounting
nut : 7 Nm

Fixed socket , nut fixing , with key (G) ,
round flange , vacuumtight .
Series 2W , multipole (12)

ETUDE N° E6212

Echelle

—

Dessiné	27.03.09	OVU /JPBA
Contrôle	27.03.09	JPBA/ CDE
Modif.	00	27.03.09 / OVU



LEMO

CH-1024 Ecublens

HVG.2W.312.CLLPV