


|                      |                       |                              |
|----------------------|-----------------------|------------------------------|
| Outer shell          | : Brass (UNS C38500)  | Black chrome                 |
| Latch sleeve         | : Bronze (UNS C54400) | Nickel plated (FS-QQ-N-290A) |
| Collet nut           | : Brass (UNS C38500)  | Black chrome                 |
| Insulator            | : PEEK                | -                            |
| Female contact       | : Bronze (UNS C54400) | Gold plated (ISO 4523)       |
| Male contact         | : Brass (UNS C38500)  | Gold plated (ISO 4523)       |
| O-rings              | : Silicone (MVQ)      | -                            |
| Other metallic parts | : Brass (UNS C38500)  | Nickel plated (FS-QQ-N-290A) |

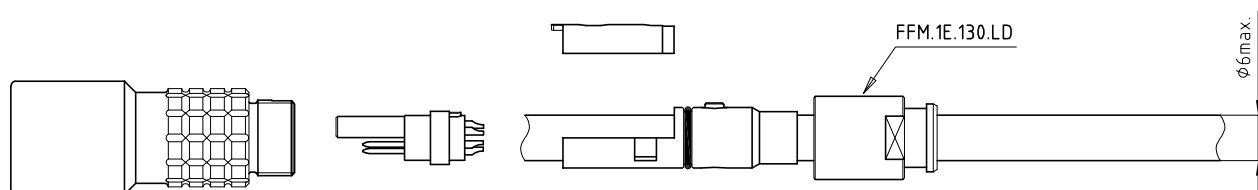

Flat spanners set : DCP.91.001.TN

Assembly instruction per document : n°  
Maximum torque mounting collet nut : 0.8 Nm

**Straight socket , with keys (L) , with collet for resin fixing and nut for bend relief .**

**Series 1L , multipole (6)**

ETUDE N° E2802

|              |          |            |                  |
|--------------|----------|------------|------------------|
| Echelle<br>— | Dessiné  | 27.03.2002 | OVU / RMO        |
|              | Contrôle | 15.04.2014 | JPBA / ATVI      |
|              | Modif.   | 02         | 15.04.2014 / OVU |



**LEMO**

CH-1024 Ecublens

**PHL.1L.306.KLLT61Z**