



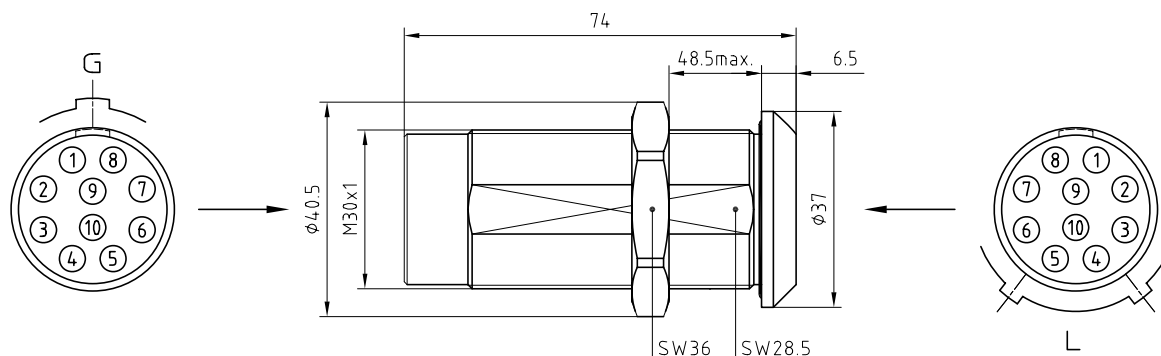

Outer shell	: Stainless steel (AISI304L)	-
Earthing crown	: Stainless steel (AISI416)	-
Insulators	: PEEK	-
Male-female contact	: Bronze (UNS C54400)	Gold plated (ISO 4523)
Hexagonal nut	: Stainless steel (AISI304L)	-
Other metallic parts	: Brass (UNS C38500)	Nickel plated (FS-QQ-N-290A)
Sealing resin	: Epoxy	-
O-Rings	: Viton (FPM)	-

Panel cut-out

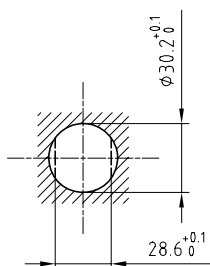

Torque for
mounting
nut : 17 Nm

Fixed coupler , nut fixing , with keys (L) at the flange
end and key (G) at the other end , vacuumtight .
Series 4K , multipole (10)

ETUDE N° E2791

Echelle

—

Dessiné 16.06.09 OVU / JPBA

Contrôle 16.06.09 JPBA/ CDE

Modif. 00 16.06.09 / OVU



LEMO

CH-1024 Ecublens

SLG.4K.310.TLAPV